


Formed Wire Deadend for Bezinal® Guy Strand 1/4"

By FARGO
Catalog # [BDE9104](#)

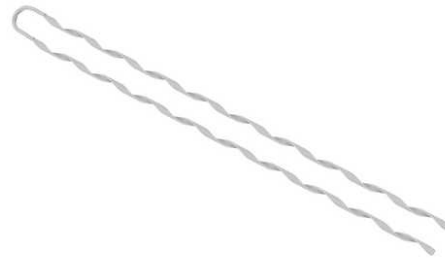

Formed Wire Deadend for 1/4" Bezinal® Guy Strand

*Representative Image

Features

- For Bezinal® Guy Strand
- Bezinal® (B-coat) wire construction
- 6,650lb (29.6kN) maximum RBS

Application

Deadend for Bezinal® Guy Strand

General

Color Code	Yellow
Material	Zinc-Aluminum Coated Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359506119

Dimensions

Length	25 in
Nominal Guy Wire Size	1/4" Bezinal®
Weight	0.480 lb

Conductor Related

Conductor Diameter - Maximum	0.259 in
Conductor Diameter - Minimum	0.231 in
Conductor Diameter Range	0.231 - 0.259
Conductor Type	Bezinal® and other common Zinc-Aluminum coated strand
Guy Wire Type	Bezinal® and other common Zinc-Aluminum coated strand

Logistics

Carton Quantity	50
Pallet Quantity	1400

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - SF05122E_0319_Formed Wire Deadend](#)
[Sales Drawings - BDE Formed Wire Deadend](#)

Related Products

[BDE9103 - Formed Wire Deadend for Bezinal® Guy Strand 7/32"](#)
[BDE9105 - Formed Wire Deadend for Bezinal® Guy Strand 9/32"](#)