


## Formed Wire Deadend for Bezinal® Guy Strand 5/16"

By FARGO  
Catalog # [BDE9106](#)

Formed Wire Deadend for 5/16" Bezinal® Guy Strand

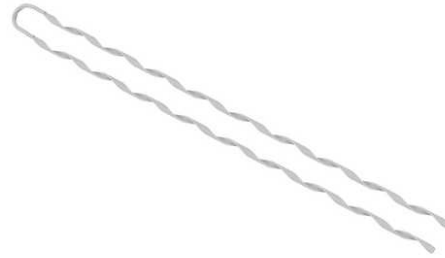

\*Representative Image

### Features

- For Bezinal® Guy Strand
- Bezinal® (B-coat) wire construction
- 11,200lb (49.8kN) maximum RBS

### Application

Deadend for Bezinal® Guy Strand

### General

Color Code	Black
Material	Zinc-Aluminum Coated Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359506126

### Dimensions

Length	31 in
Nominal Guy Wire Size	5/16" Bezinal®
Weight	0.820 lb

### Conductor Related

Conductor Diameter - Maximum	0.336 in
Conductor Diameter - Minimum	0.292 in
Conductor Diameter Range	0.292 - 0.336
Conductor Type	Bezinal® and other common Zinc-Aluminum coated strand
Guy Wire Type	Bezinal® and other common Zinc-Aluminum coated strand

### Logistics

Carton Quantity	50
-----------------	----

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Literature - SF05122E\\_0319\\_Formed Wire Deadend](#)  
[Sales Drawings - BDE Formed Wire Deadend](#)

### Related Products

[BDE9107 - Formed Wire Deadend for Bezinal® Guy Strand 3/8"](#)  
[BDE9105 - Formed Wire Deadend for Bezinal® Guy Strand 9/32"](#)