


Formed Wire Deadend for Bezinal® Guy Strand 3/8"

By FARGO
Catalog # [BDE9107](#)

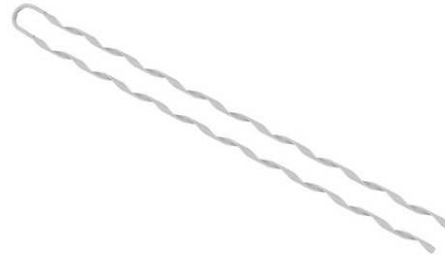

Formed Wire Deadend for 3/8" Bezinal® Guy Strand

*Representative Image

Features

- For Bezinal® Guy Strand
- Bezinal® (B-coat) wire construction
- 15,400lb (68.5kN) maximum RBS

Application

Deadend for Bezinal® Guy Strand

General

Color Code	Orange
Material	Zinc-Aluminum Coated Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359506133

Dimensions

Dimensions	35.000 in x 0.500 in x 3.125 in
Height	3.125 in
Length	35.000 in
Nominal Guy Wire Size	3/8" Bezinal®
Weight	1.060 lb
Width	0.500 in

Conductor Related

Conductor Diameter - Maximum	0.394 in
Conductor Diameter - Minimum	0.337 in
Conductor Diameter Range	0.337 - 0.394
Conductor Type	Bezinal® and other common Zinc-Aluminum coated strand
Guy Wire Type	Bezinal® and other common Zinc-Aluminum coated strand

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - SF05122E_0319_Formed Wire Deadend](#)
[Sales Drawings - BDE Formed Wire Deadend](#)

Related Products

[BDE9106 - Formed Wire Deadend for Bezinal® Guy Strand 5/16"](#)
[BDE9108 - Formed Wire Deadend for Bezinal® Guy Strand 7/16"](#)