


HUBBELL

Power Systems

Formed Wire False Deadend for Bezinal® Guy Strand 3/8"

By FARGO
Catalog # [BFDE9107](#)

Formed Wire False Deadend for 3/8" Bezinal® Guy Strand

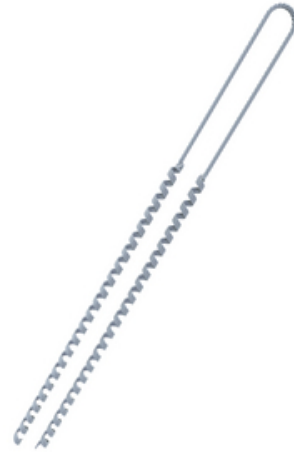

Features

- Allows strand to continue beyond the deadend pole
- For Bezinal® Guy Strand
- Bezinal® (B-coat) wire construction
- 15,400lb (68.5KN) maximum RBS

General

Application	False Deadend for Bezinal® Guy Strand
Color Code	Orange
Material	Zinc-Aluminum Coated Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359710974

Dimensions

Length	42 in
Nominal Guy Wire Size	3/8" Bezinal®
Weight	1.185 lb

Conductor Related

Conductor Diameter - Maximum	0.394 in
Conductor Diameter - Minimum	0.337 in
Conductor Diameter Range	0.337 - 0.394
Conductor Type	Bezinal®
Guy Wire Type	Bezinal®

Logistics

Carton Quantity	25
Pallet Quantity	1400

Product Assets

[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - Formed Wire False Deadend](#)
[Sales Drawings - FWFDE/BFDE - Formed Wire False Deadends](#)



A Hubbell brand