


## Compression Splice Uni-Grip®(One Die) Full Tension

By FARGO  
Catalog # [C151212](#)

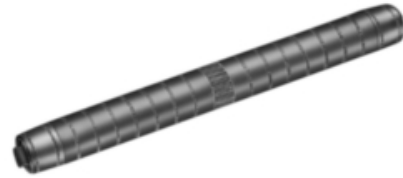

"Compression Terminal, Uni-Grip, Jumper Terminal, 15 degree, For ACSR,AAC,AAAC,ACAR. Standard Aluminum Range: 1.806"-1.900", Compact/TW range: 1.662"-1.710"

\*Representative Image

### Features

- "For use with AAC Anemone
- Full tension Splice assembly
- Splices are prefilled with Inhibitor
- For Extra Length Repair Splice Add "XL" Suffix and Repair Cutoff Length in Inches e.g. C151212XL24
- Splices are EHV rated where conductor dia. is 1" or larger"

### General

Compression Method	Uni-Grip (single die system)
Die Size	12CD
EU RoHS Indicator	No
Material	Aluminum Alloy
Press Minimum	60 to
UPC	096359294221

### Dimensions

Length Before Compression	14.4 in
Messenger Diameter Range	0 - 0
Weight	2.205 lb

### Electrical Ratings

Voltage Application	EHV; Standard
---------------------	---------------

### Conductor Related

Conductor Compatibility	AAC-Cockscomb-900-37;AAC-Snapdragon-900-61;AAC-Magnolia-954-37;AAC-Goldenrod-954-61
Conductor Diameter (Main) Range	0 - 0
Conductor Diameter - Maximum	1.14 in
Conductor Diameter - Minimum	1.046 in
Conductor Diameter Range	1.046 - 1.14
Conductor Type	AAC

### Certifications and Compliance

UL Listed	No
-----------	----

### Product Assets

[Catalogs - Transmission Connectors Catalog - Full \(CA05063E\)](#)