


Compression Splice Uni-Grip®(One Die) Full Tension

By FARGO
Catalog # [C151313](#)

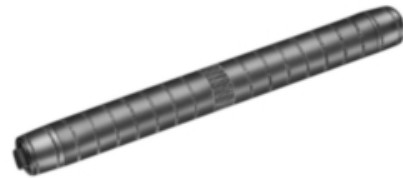

"Compression Jumper Terminal, Straight, Conductor Dia. Range 0.752"-0.814" For ACSR,AAAC,AAC,ACAR, Material: Aluminum alloy"

*Representative Image

Features

- "For use with AAC Hawkweed
- Full tension Splice assembly
- Splices are prefilled with Inhibitor
- For Extra Length Repair Splice Add "XL" Suffix and Repair Cutoff Length in Inches e.g. C151313XL24
- Splices are EHV rated where conductor dia. is 1" or larger"

General

Compression Method	Uni-Grip (single die system)
Die Size	13CD
EU RoHS Indicator	No
Material	Aluminum Alloy
Press Minimum	60 to
UPC	096359294238

Dimensions

Length Before Compression	15.6 in
Messenger Diameter Range	0 - 0
Weight	1.813 lb

Electrical Ratings

Voltage Application	EHV; Standard
---------------------	---------------

Conductor Related

Conductor Compatibility	AAC-Camellia-1000-61;AAC-Bluebell-1033.5-37;AAC-Larkspur-1033.5-61;AAC-Marigold-1113-61
Conductor Diameter (Main) Range	0 - 0
Conductor Diameter - Maximum	1.235 in
Conductor Diameter - Minimum	1.141 in
Conductor Diameter Range	1.141 - 1.235
Conductor Type	AAC

Certifications and Compliance

UL Listed	No
-----------	----

Product Assets

[Catalogs - Transmission Connectors Catalog - Full \(CA05063E\)](#)