


## Formed Wire Deadend for Guy Strand 1/4"

By FARGO  
Catalog # [FWDE1104](#)

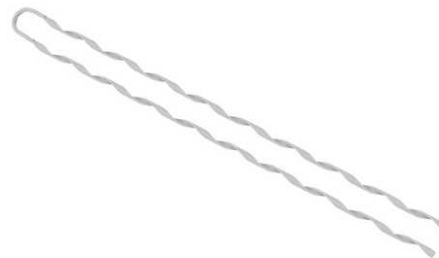

Formed Wire Deadend for 1/4" Guy Strand

\*Representative Image

### Features

- For HSS, EHS, Common, Siemens-Martin, Utilities and Bell System Strand grades
- Zinc plated (B-coat) EHS steel construction
- 6650lb (29.6KN) maximum RBS

### Application

Deadend for Guy Strand

### General

Color Code	Yellow
Material	Galvanized Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359366065

### Dimensions

Dimensions	25.000 in x 0.377 in x 2.754 in
Height	2.754 in
Length	25.000 in
Nominal Guy Wire Size	1/4" 7 Strand
Weight	0.480 lb
Width	0.377 in

### Conductor Related

Conductor Diameter - Maximum	0.259 in
Conductor Diameter - Minimum	0.231 in
Conductor Diameter Range	0.231 - 0.259
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

### Logistics

Carton Quantity	50
Pallet Quantity	1400

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Literature - SF05122E\\_0319\\_Formed Wire Deadend](#)  
[Sales Drawings - FWDE Formed Wire Deadend](#)  
[Video - HPS Formed Wire Dead End Install \(VI05011E\)](#)

### Related Products

[FWDE1105 - Formed Wire Deadend for Guy Strand 9/32"](#)  
[FWDE1103 - Formed Wire Deadend for Guy Strand 7/32"](#)