


Formed Wire Deadend for Guy Strand 1/4"

By FARGO
Catalog # [FWDE1104TE](#)

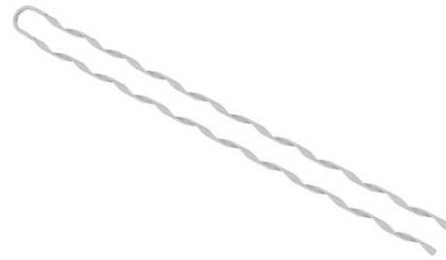

Formed Wire Deadend for 1/4" Guy Strand, Tapered Ends

*Representative Image

Features

- For HSS, EHS, Common Siemens-Martin; Utilities and Bell System Strand grades; Zinc plated (B-coat) EHS steel construction; Tapered Ends; 6650lb (29.6KN) maximum RBS

Application

Deadend for Guy Strand

General

Color Code	Yellow
EU RoHS Indicator	No
Material	Galvanized Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359375579

Dimensions

Length	25 in
Nominal Guy Wire Size	1/4" 7 Strand
Weight	0.440 lb

Conductor Related

Conductor Diameter - Maximum	0.259
Conductor Diameter - Minimum	0.231
Conductor Diameter Range	0.231 - 0.259
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

Logistics

Carton Quantity	50
Pallet Quantity	1400

Product Assets

[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - FWDE_TE_Sales Drawing](#)
[Video - HPS Formed Wire Dead End Install \(VI05011E\)](#)