


Formed Wire Deadend for Guy Strand 7/16"

By FARGO
Catalog # [FWDE1108TE](#)

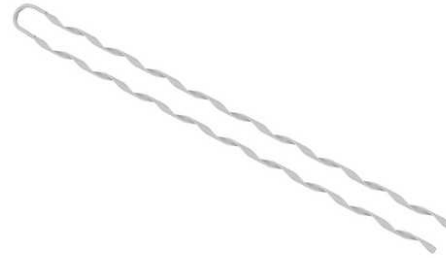

Formed Wire Deadend for 7/16" Guy Strand, Tapered Ends

*Representative Image

Features

- For HSS, EHS, Common Siemens-Martin; Utilities and Bell System Strand grades; Zinc plated (B-coat) EHS steel construction; Tapered Ends; 20800lb (92.5KN) maximum RBS

Application

Deadend for Guy Strand

General

Color Code	Green
Material	Galvanized Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359375609

Dimensions

Dimensions	38.000 in x 0.598 in x 3.446 in
Height	3.446 in
Length	38.000 in
Nominal Guy Wire Size	7/16" 7 Strand
Weight	1.440 lb
Width	0.598 in

Conductor Related

Conductor Diameter - Maximum	0.474
Conductor Diameter - Minimum	0.395
Conductor Diameter Range	0.395 - 0.474
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

Logistics

Carton Quantity	25
Pallet Quantity	700

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - FWDE_TE_Sales Drawing](#)
[Video - HPS Formed Wire Dead End Install \(VI05011E\)](#)