


HUBBELL

Power Systems

Formed Wire Line Splice for Guy Strand 3/16"

By FARGO
Catalog # [FWLS2102](#)

Formed Wire Line Splice for 3/16" Guy Strand

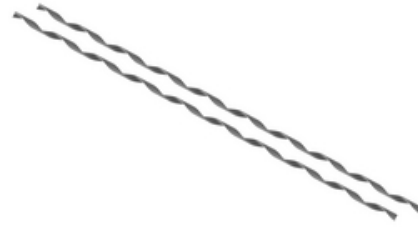

*Representative Image

Features

- For HSS, EHS, Common, Siemens-Martin, Utilities and Bell System Strand grades
- Zinc plated (B-coat) EHS steel construction
- 3,990lb (17.7kN) maximum RBS

General

Application	Line Splice for Guy Strand
Catalog Number	FWLS2102
Color Code	Red
Material	Galvanized Steel
Product Category	Splices
Type	Formed Wire
UPC	096359576471

Dimensions

Length	27 in
Nominal Guy Wire Size	3/16" 7 Strand
Weight	0.47 lb

Conductor Related

Conductor Diameter - Maximum	0.203 in
Conductor Diameter - Minimum	0.174 in
Conductor Diameter Range	0.174 - 0.203
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

Logistics

Carton Quantity	100
-----------------	-----

Product Assets

[Sales Drawings - FWLS Formed Wire Guy Splice](#)



A Hubbell brand