


## Formed Wire Line Splice for Guy Strand 7/32"

By FARGO  
Catalog # [FWLS2103](#)

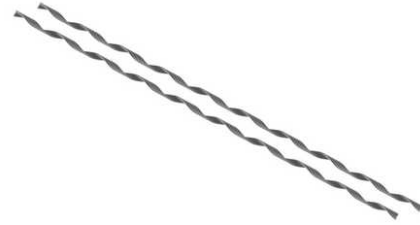

Formed Wire Line Splice for 7/32" Guy Strand

\*Representative Image

### Features

- For HSS, EHS, Common, Siemens-Martin, Utilities and Bell System Strand grades
- Zinc plated (B-coat) EHS steel construction
- 5,400lb (24.0kN) maximum RBS

### Application

Line Splice for Guy Strand

### General

Color Code	Green
Material	Galvanized Steel
Product Category	Splices
Type	Formed Wire
UPC	096359576488

### Dimensions

Length	29 in
Nominal Guy Wire Size	7/32" 7 Strand
Weight	0.630 lb

### Conductor Related

Conductor Diameter - Maximum	0.23
Conductor Diameter - Minimum	0.204
Conductor Diameter Range	0.204 - 0.23
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

### Logistics

Carton Quantity	100
-----------------	-----

### Product Assets

[Sales Drawings - FWLS Formed Wire Guy Splice](#)