


Formed Wire Line Splice for Guy
Strand 1/4"

By FARGO
Catalog # FWLS2104

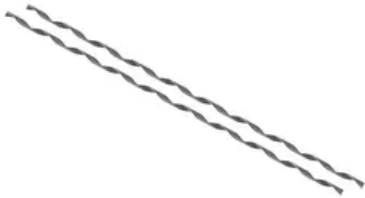

Formed Wire Line Splice for 1/4" Guy Strand

*Representative Image

Features

- For HSS, EHS, Common, Siemens-Martin, Utilities and Bell System Strand grades
- Zinc plated (B-coat) EHS steel construction
- 6,650lb (29.6kN) maximum RBS

Application

Line Splice for Guy Strand

General

Catalog Number	FWLS2104
Color Code	Yellow
Material	Galvanized Steel
Product Category	Splices
Type	Formed Wire
UPC	096359576495

Dimensions

Dimensions	35.000 in x 0.377 in x 0.377 in
Height	0.377 in
Length	35 in
Nominal Guy Wire Size	1/4" 7 Strand

Weight	0.68 lb
Width	0.377 in

Conductor Related

Conductor Diameter - Maximum	0.259 in
Conductor Diameter - Minimum	0.231 in
Conductor Diameter Range	0.231 - 0.259
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	---

Logistics

Carton Quantity	50
Pallet Quantity	2450

Product Assets

[Catalogs - Distribution Connectors](#)
[Sales Drawings - FWLS Formed Wire Guy Splice](#)
[Specifications - FWLS2104](#)