


Formed Wire Line Splice for Guy Strand 9/32"

By FARGO
Catalog # FWLS2105

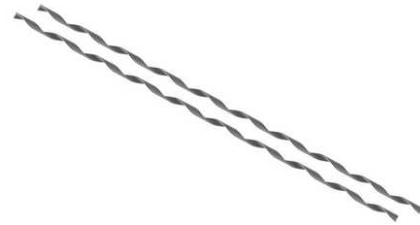

Formed Wire Line Splice for 9/32" Guy Strand

*Representative Image

Features

- For HSS, EHS, Common, Siemens-Martin, Utilities and Bell System Strand grades
- Zinc plated (B-coat) EHS steel construction
- 8,950lb (39.8kN) maximum RBS

Application

Line Splice for Guy Strand

General

Color Code	Blue
Material	Galvanized Steel
Product Category	Splices
Type	Formed Wire
UPC	096359576501

Dimensions

Length	38 in
Nominal Guy Wire Size	9/32" 7 Strand
Weight	0.730 lb

Conductor Related

Conductor Diameter - Maximum	0.291
Conductor Diameter - Minimum	0.26
Conductor Diameter Range	0.26 - 0.291
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

Logistics

Carton Quantity	50
-----------------	----

Product Assets

[Sales Drawings - FWLS Formed Wire Guy Splice](#)