


# HUBBELL

## Power Systems

### Formed Wire Line Splice for Guy Strand 3/8"

By FARGO  
Catalog # [FWLS2107](#)

Formed Wire Line Splice for 3/8" Guy Strand

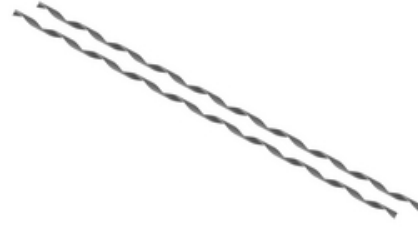

\*Representative Image

#### Features

- For HSS, EHS, Common, Siemens-Martin, Utilities and Bell System Strand grades
- Zinc plated (B-coat) EHS steel construction
- 15,400lb (68.5kN) maximum RBS

#### General

Application	Line Splice for Guy Strand
Catalog Number	FWLS2107
Color Code	Orange
Material	Galvanized Steel
Product Category	Splices
Type	Formed Wire
UPC	096359576525

#### Dimensions

Length	50 in
Nominal Guy Wire Size	3/8" 7 Strand
Weight	1.5 lb

#### Conductor Related

Conductor Diameter - Maximum	0.394 in
Conductor Diameter - Minimum	0.337 in
Conductor Diameter Range	0.337 - 0.394
Conductor Type	Galvanized Steel
Guy Wire Type	Galvanized Steel

#### Logistics

Carton Quantity	25
Pallet Quantity	750

#### Product Assets

[Sales Drawings - FWLS Formed Wire Guy Splice](#)



A Hubbell brand