


Formed Wire Line Splice for Guy  
Strand 9/16"

By FARGO  
Catalog # FWLS2110

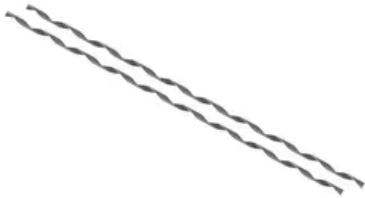

Formed Wire Line Splice for 9/16" Guy Strand

\*Representative Image

Features

- For HSS, EHS, Common, Siemens-Martin, Utilities and Bell System Strand grades
- Zinc plated (B-coat) EHS steel construction
- 35,000lb (155.7kN) maximum RBS

Application

Line Splice for Guy Strand

General

|                  |                  |
|------------------|------------------|
| Catalog Number   | FWLS2110         |
| Color Code       | Yellow           |
| Material         | Galvanized Steel |
| Product Category | Splices          |
| Type             | Formed Wire      |
| UPC              | 096359576556     |

Dimensions

|                              |                  |
|------------------------------|------------------|
| Length                       | 71 in            |
| Nominal Guy Wire Size        | 9/16" 7 Strand   |
| Weight                       | 5.6 lb           |
| Conductor Related            |                  |
| Conductor Diameter - Maximum | 0.57 in          |
| Conductor Diameter - Minimum | 0.516 in         |
| Conductor Diameter Range     | 0.516 - 0.57     |
| Conductor Type               | Galvanized Steel |
| Guy Wire Type                | Galvanized Steel |

Logistics

|                 |    |
|-----------------|----|
| Carton Quantity | 10 |
|-----------------|----|

Product Assets

[Sales Drawings - FWLS Formed Wire Guy Splice](#)  
[Specifications - FWLS2110](#)