


Hot Line Connector

By FARGO
Catalog # [GA103L](#)

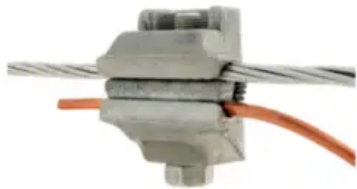

Overhead Primary Tap Connector, Hot Line Tap Connector,
Aluminum, AAC|AAAC|ACSR, Range 0.25 - 0.563 in

*Representative Image

Features

For full duty connections involving major line equipment and
apparatus or main to main connections.

General

Bolt Installation Torque (Recommended)	0 ft-lbs
Catalog Number	GA103L
Material	Aluminum
Material - Eyebolt	Aluminum Alloy
Material - Eyestem	Forged Aluminum Alloy
Material - Spring (on Eyestem)	Stainless Steel Bellville
Plating	No
UPC	096359304173

Dimensions

Bolt Diameter	0.38
Dimensions	4.500 in x 2.500 in x 5.750 in
Height	5.75 in
Length	4.5 in
Weight	0.88 lb
Width	2.5 in

Electrical Ratings

Maximum Current Rating Amps Continuous	Rated for maximum current of both Main & Tap Conductors
---	--

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR- Swan-4-6/1;ACSR-Swanate-4- 7/1;ACSR-Sparrow-2-6/1;ACSR-
-------------------------	---

Sparate-2-7/1;ACSR-Robin-1-
6/1;ACSR-Raven-1/0-6/1;ACSR-
Quail-2/0-6/1;ACSR-Pigeon-
3/0-6/1;ACSR-Penguin-4/0-
6/1;AAC-Peachbell-6-7;AAC-
Rose-4-7;AAC-Iris-2-7;AAC-
Pansy-1-7;AAC-Poppy-1/0-
7;AAC-Aster-2/0-7;AAC-Phlox-
3/0-7;AAC-Oxlip-4/0-7;AAAC
6201 Alloy-Akron-30.58-
6/18;AAAC 6201 Alloy-Alton-
48.69-6/18;AAAC 6201 Alloy-
Ames-77.47-6/18;AAAC 6201
Alloy-Azusa-123.3-6/18;AAAC
6201 Alloy-Anaheim-155.4-
6/18;AAAC 6201 Alloy-
Amherst-195.7-6/18

Conductor Diameter (Tap) - Maximum	0.563 in
Conductor Diameter (Tap) - Minimum	0.232 in
Conductor Diameter - Maximum	0.563 in
Conductor Diameter - Minimum	0.232 in
Conductor Diameter Range	0.232 - 0.563

Logistics

Packaging Type	Bag
Pallet Quantity	1200

Product Assets

[Catalogs - Distribution Connectors](#)
[Specifications - GA103L](#)