


Hot Line Connector

By FARGO
Catalog # [GA1074L](#)

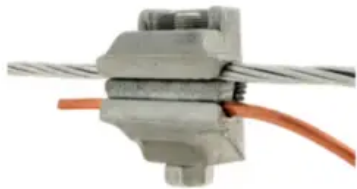

Overhead Primary Tap Connector, Hot Line Tap Connector,
Aluminum, AAC|AAAC|ACSR, Range 0.642 - 0.883 in

*Representative Image

Features

For full duty connections involving major line equipment and
apparatus or main to main connections.

General

Bolt Installation Torque (Recommended)	0 ft-lbs
Catalog Number	GA1074L
Material	Aluminum
Material - Eyebolt	Aluminum Alloy
Material - Eystem	Forged Aluminum Alloy
Material - Spring (on Eystem)	Stainless Steel Bellville
Plating	No
UPC	096359304258

Dimensions

Bolt Diameter	0.38
Weight	1.058 lb

Electrical Ratings

Maximum Current Rating Amps Continuous	Rated for maximum current of both Main & Tap Conductors
---	--

Conductor Related

Conductor Compatibility	ACSR-Robin-1-6/1;ACSR- Raven-1/0-6/1;ACSR-Quail-2/0- 6/1;ACSR-Pigeon-3/0- 6/1;ACSR-Partridge-266.8- 26/7;ACSR-Ostrich-300- 26/7;ACSR-Merlin-336.4- 18/1;ACSR-Linnet-336.4- 26/7;ACSR-Oriole-336.4- 30/7;ACSR-Chickadee-397.5- 18/1;ACSR-Brant-397.5- 24/7;ACSR-Ibis-397.5- 26/7;ACSR-Lark-397.5- 30/7;ACSR-Pelican-477-
-------------------------	---

18/1;ACSR-Flicker-477-
24/7;ACSR-Hawk-477-
26/7;ACSR-Hen-477-
30/7;ACSR-Osprey-556.5-
18/1;ACSR-Brahma-203.2-
16/19;AAC-Poppy-1/0-7;AAC-
Aster-2/0-7;AAC-Phlox-3/0-
7;AAC-Oxlip-4/0-7;AAC-
Daffodil-350-19;AAC-Canna-
397.5-19;AAC-Cosmos-477-
19;AAC-Syringa-477-37;AAC-
Zinnia-500-19;AAC-Hyacinth-
500-37;AAC-Dahlia-556.5-
19;AAC-Mistletoe-556.5-
37;AAAC 6201 Alloy-Azusa-
123.3-6/18;AAAC 6201 Alloy-
Anaheim-155.4-6/18;AAAC 6201
Alloy-Amherst-195.7-6/18

Conductor Diameter (Tap) - Maximum	0.741 in
Conductor Diameter (Tap) - Minimum	0.257 in
Conductor Diameter - Maximum	0.893 in
Conductor Diameter - Minimum	0.642 in
Conductor Diameter Range	0.642 - 0.893

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	--

Logistics

Packaging Type	Bag
Pallet Quantity	800

Product Assets

[Catalogs - Distribution Connectors](#)
[Specifications - GA1074L](#)