


Connector, Vise-Type

By FARGO
Catalog # [GA9020LSS](#)

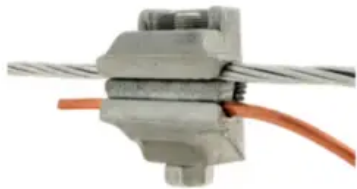

Single Bolt Aluminum Vise-Type Connector

*Representative Image

Features

- Recommended for aluminum or aluminum to copper distribution, service or tap connections
- Sealant is recommended on all connectors
- Optional snap-on cover available

General

Bolt Head Type	0.56 in (14 mm)
Bolt Installation Torque (Recommended)	0 ft-lbs
Catalog Number	GA9020LSS
Grommets	No
Material	Aluminum
Material - Body	Aluminum Alloy
Material - Hardware	Stainless Steel
Material - Spacer	Aluminum
Plating	No
Product Category	Vise Type Connectors
Style	Single Bolt
UPC	096359304753

Dimensions

Bolt Diameter	0.38
Diameter - Bolt	0.38 in
Dimensions	1.250 in x 1.875 in x 2.375 in
Height	2.375 in
Length	1.25 in
Length - Nut Flat-To-Flat	0.56 in
Weight	0.31 lb
Width	1.875 in

Conductor Related

Conductor Compatibility	ACSR-Turkey-6-6/1;ACSR-Swan-4-6/1;ACSR-Swanate-4-7/1;ACSR-Sparrow-2-6/1;ACSR-Sparate-2-7/1;ACSR-Robin-1-6/1;ACSR-Raven-1/0-6/1;AAC-Peachbell-6-7;AAC-Rose-4-7;AAC-Iris-2-7;AAC-Pansy-1-7;AAC-Poppy-1/0-7;AAC-Aster-2/0-7;AAAC 6201 Alloy-Akron-30.58-6/18;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18;AAAC 6201 Alloy-Azusa-123.3-6/18
Conductor Diameter (Tap) - Maximum	0.447 in
Conductor Diameter (Tap) - Minimum	0.162 in
Conductor Diameter - Maximum	0.447 in
Conductor Diameter - Minimum	0.162 in
Conductor Diameter Range	0.162 - 0.447

Certifications And Compliance

UL Listed	No
-----------	----

Logistics

Pallet Quantity	6400
-----------------	------

Product Assets

- [Catalogs - Distribution Connectors](#)
- [Sales Drawings - CC-20308](#)
- [Specifications - GA9020LSS](#)