


Grounding Clamp, #5 Sol. - #2 Sol.

By FARGO
Catalog # [GC5002S](#)

Grounding Clamp, Copper Cable to Cable, Vice Type.

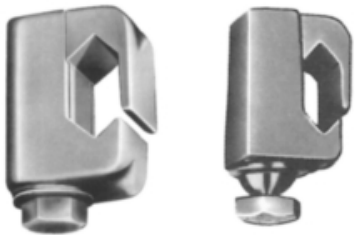

*Representative Image

Features

- For copper connections
- One piece design for easier, faster installation
- Vise design achieves high connector pressure with low wrench force

General

Bolt Head Type	Hex
Bolt Installation Torque (Recommended)	180 in-lbs
Inhibitor Loaded	No
Material	Bronze
Material - Body	Bronze
Material - Bolt	Stainless Steel
Material - Hardware	Stainless Steel
Material - Keeper	Bronze
Plating	No
Product Category	Vise Type Connectors
UPC	096359307402

Dimensions

Bolt Diameter	<ul style="list-style-type: none">• 0.313 in• 0.313 in
Diameter - Bolt	0.3125 in
Diameter - Bolt Head	0.375 in
Dimensions	1.000 in x 0.750 in x 1.625 in
Height	1.625 in
Length	1.000 in
Weight	0.216 lb
Width	0.750 in

Conductor Related

Conductor Diameter (Main) - Maximum	0.32 in
Conductor Diameter (Main) - Minimum	0.181 in
Conductor Diameter (Tap) - Maximum	0.32 in
Conductor Diameter (Tap) - Minimum	0.181 in
Conductor Type	Copper

Logistics

Pallet Quantity	8000
-----------------	------

Product Assets

- [Catalogs - Distribution Connectors \(CA05127E\)](#)
- [Sales Drawings - CC-25775](#)
- [Video - Hubbell Powet Systems Vice Type Clamp \(VI0593E\)](#)
- [Video - Hubbell Power Systems Bolted Parallel Groove, Vise Type, and U Bolt Clamps \(VI05052E1019\)](#)

