


HUBBELL

Power Systems

Grounding Clamp, #10 Sol. - #6 Sol., Slotted Hex Head

By FARGO
Catalog # [GC5006SH](#)

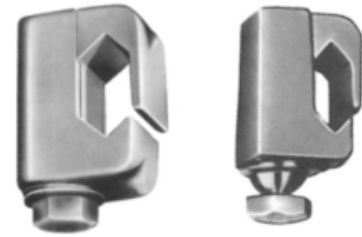

Grounding Clamp, Copper Cable to Cable, Vice Type.

*Representative Image

Features

- For copper connections
- One piece design for easier, faster installation
- Vise design achieves high connector pressure with low wrench force
- Slotted-Head bolt.

General

Bolt Head Type	Hex
Bolt Installation Torque (Recommended)	240 in-lbs
Catalog Number	GC5006SH
Inhibitor Loaded	No
Material	Bronze
Material - Body	Bronze
Material - Bolt	Stainless Steel
Material - Hardware	Stainless Steel
Material - Keeper	Bronze
Plating	No
Product Category	Vise Type Connectors
Slotted-Head Bolt	Yes
UPC	096359307488

Dimensions

Bolt Diameter	0.25 in
	0.25 in
Diameter - Bolt	0.25 in
Diameter - Bolt Head	0.3125 in
Dimensions	0.750 in x 0.625 in x 1.000 in
Height	1 in
Length	0.75 in
Weight	0.088 lb
Width	0.625 in

Conductor Related

Conductor Diameter (Main) - Maximum	0.162 in
Conductor Diameter (Main) - Minimum	0.101 in
Conductor Diameter (Tap) - Maximum	0.162 in
Conductor Diameter (Tap) - Minimum	0.101 in
Conductor Type	Copper

Logistics

Pallet Quantity	12000
-----------------	-------

Product Assets

- [Catalogs - Distribution Connectors](#)
- [Sales Drawings - CC-25775](#)
- [Video - Hubbell Power Systems Vice Type Clamp](#)
- [Video - Hubbell Power Systems Bolted Parallel Groove, Vise Type, and U Bolt Clamps](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
FG-GC5006SH-SPEC-EN | REV 6/2024