


Grounding Clamp, #11 Sol. - #8 Str., Slotted Hex Head

By FARGO
Catalog # GC5008SH

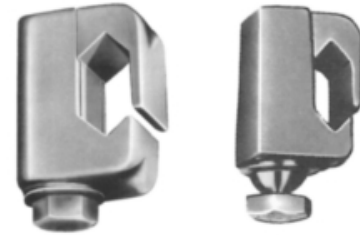

Grounding Clamp, Copper Cable to Cable, Vice Type.

*Representative Image

Features

- For copper connections
- One piece design for easier, faster installation
- Vise design achieves high connector pressure with low wrench force
- Slotted-Head bolt.

General

Bolt Head Type	Hex
Bolt Installation Torque (Recommended)	50 in-lbs
Inhibitor Loaded	No
Material	Bronze
Material - Body	Bronze
Material - Bolt	Stainless Steel
Material - Hardware	Stainless Steel
Material - Keeper	Bronze
Plating	No
Product Category	Vise Type Connectors
Slotted-Head Bolt	Yes
UPC	096359307495

Dimensions

Bolt Diameter	0.250 in
Diameter - Bolt	0.250 in
Diameter - Bolt Head	0.3125 in
Height	0.875 in
Length	0.625 in

Conductor Related

Conductor Diameter (Main) - Maximum	0.146 in
Conductor Diameter (Main) - Minimum	0.091 in
Conductor Diameter (Tap) - Maximum	0.146 in
Conductor Diameter (Tap) - Minimum	0.091 in
Conductor Type	Copper

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Video - Hubbell Power Systems Vice Type Clamp \(VI0593E\)](#)
[Video - Hubbell Power Systems Bolted Parallel Groove, Vise Type, and U Bolt Clamps \(VI05052E1019\)](#)