


## Connector, Vise-Type

By FARGO  
Catalog # [GC8010GL](#)

Single Bolt Bronze Vise-Type Connector with Spacer

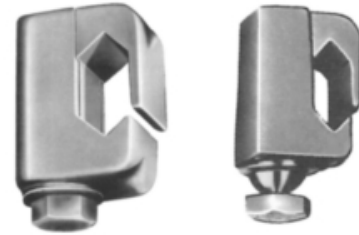

\*Representative Image

### Features

- Will accept two maximum sized conductors.

### General

Bolt Head Type	Hex
Bolt Installation Torque (Recommended)	240 in-lbs
Grommets	Yes
Inhibitor Loaded	Yes
Material	Bronze
Material - Body	Bronze
Material - Bolt	Stainless Steel
Material - Hardware	Stainless Steel
Material - Keeper	Bronze
Material - Spacer	Bronze
Plating	No
Product Category	Vise Type Connectors
UPC	096359307723

### Dimensions

Bolt Diameter	0.313 in
Diameter - Bolt	0.3125 in
Diameter - Bolt Head	0.56 in
Dimensions	1.000 in x 1.375 in x 1.500 in
Height	1.500 in
Length	1.000 in
Length - Nut Flat-To-Flat	0.56 in
Weight	0.250 lb
Width	1.375 in

### Conductor Related

Conductor Diameter (Main) - Maximum	0.325 in
Conductor Diameter (Main) - Minimum	0.128 in
Conductor Diameter (Main) - Range	0.128 - 0.325
Conductor Diameter (Tap) - Maximum	0.325 in
Conductor Diameter (Tap) - Minimum	0.128 in
Conductor Type	Copper

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Sales Drawings - CC-25843](#)

### Related Products

[GC8040PGL - Connector, Vise-Type](#)  
[GC8002GL - Connector, Vise-Type](#)  
[GC8010PGL - Connector, Vise-Type](#)  
[GC8020GL - Connector, Vise-Type](#)  
[GC8040GL - Connector, Vise-Type](#)