

Aluminum Automatic Dead End, #4
AAC, #4 AAAC, #4 (6/1) ACSR
Conductor, SS Flex Bail.

By FARGO
Catalog # [GD402A](#)

Aluminum Automatic Dead End, #4 AAC, #4 AAAC, #4 (6/1)
ACSR Conductor, Diameter range .225 - .250" (5.59 - 6.35 mm),
SS Flex Bail.

Features


- Automatic Dead Ends for ACSR, AAC, and AAAC Conductor
- Galvanized steel stirrup clevis or Z-bail for primary applications and flexible or semi-flex bails for secondary applications
- Add "N" for neoprene covered Flex or Semi-flex bail
- Add "TA" for pulling eye (clevis bail only)

General

Bail Option	SS Flex Bail
Catalog Number	GD402A
Color Code	Orange
Material	Aluminum Alloy
Material - Bail	Stainless Steel
Material - Shell	High Strength Aluminum Alloy
Product Category	Flex Bail
Type	Automatic
UPC	096359308539

Dimensions

Assembly Rating (Ultimate)	0 lb
Length	12.8 in
Weight	0.2 lb
Width	2.672 in

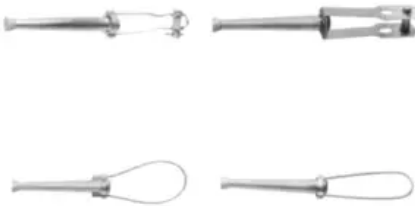

*Representative Image

Conductor Related

Conductor Compatibility	ACSR-Swan-4-6/1;AAC-Rose-4-7;AAAC 6201 Alloy-Alton-48.69-6/18
Conductor Diameter - Maximum	0.25
Conductor Diameter - Minimum	0.225
Conductor Diameter Range	0.225 - 0.25

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	---

Logistics

Pallet Quantity	4000
-----------------	------

Product Assets

[Catalogs - Distribution Connectors](#)
[Literature - Deadends For Overhead Connections](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - CC-25241](#)
[Specifications - GD402A](#)