

Aluminum Automatic Dead End, 477
AAC, 465.4 AAAC, 397.5 (18/1)
ACSR Conductor, Z Bail.

By FARGO
Catalog # [GD412Z](#)

Aluminum Automatic Dead End, 477 AAC, 465.4 AAAC,
397.5(18/1) ACSR Conductor, Diameter range .722 - .795" (18.34 -
20.19 mm), Z Bail.

Features


- Automatic Dead Ends for ACSR, AAC, and AAAC Conductor
- Galvanized steel stirrup clevis or Z-bail for primary applications and flexible or semi-flex bails for secondary applications
- Add "N" for neoprene covered Flex or Semi-flex bail
- Add "TA" for pulling eye (clevis bail only)

General

Bail Option	Z Bail
Catalog Number	GD412Z
Color Code	Blue
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum
Material - Bail	Stainless Steel
Material - Pin (Clevis)	Galvanized Steel
Material - Pin (Cotter)	Stainless Steel
Material - Shell	High Strength Aluminum Alloy
Product Category	Z Bail
Type	Automatic
UPC	096359308898

Dimensions

Assembly Rating (Ultimate)	10000 lb
----------------------------	----------

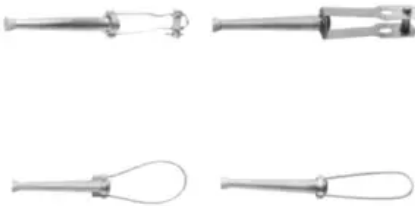

*Representative Image

Weight	2.35 lb
--------	---------

Conductor Related

Conductor Compatibility	ACSR-Oriole-336.4-30/7;ACSR-Chickadee-397.5-18/1;ACSR-Brant-397.5-24/7;ACSR-Ibis-397.5-26/7;AAC-Canna-397.5-19;AAC-Cosmos-477-19;AAC-Syringa-477-37
Conductor Diameter - Maximum	0.795
Conductor Diameter - Minimum	0.722
Conductor Diameter Range	0.722 - 0.795

Logistics

Pallet Quantity	320
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors](#)
[Literature - Deadends For Overhead Connections](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - GD-440A_Series_Overhead_Automatic_Deadend\(CC-25241\)](#)
[Specifications - GD412Z](#)