


Aluminum Automatic Dead End, #4 - #2 AAC, #4 - #2 AAAC, #4 - #2 ACSR Conductor, Clevis Bail.

By FARGO
Catalog # [GD4442A](#)

Aluminum Automatic Dead End, #4 - #2 AAC, #4 - #2 AAAC,
#4 - #2 ACSR Conductor, Diameter range .220 - .320" (5.59 -
8.13 mm), Clevis Bail.

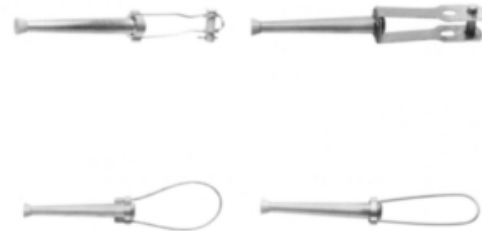

*Representative Image

Features

- Automatic Dead Ends for ACSR, AAC, and AAAC Conductor
- Galvanized steel stirrup clevis or Z-bail for primary applications and flexible or semi-flex bails for secondary applications
- Add "N" for neoprene covered Flex or Semi-flex bail
- Add "TA" for pulling eye (clevis bail only)

General

Bail Option	Clevis Bail
Color Code	Red; Orange
Material	Aluminum
Material - Bail	Galvanized Steel
Material - Pin (Clevis)	Galvanized Steel
Material - Pin (Cotter)	Stainless Steel
Material - Shell	High Strength Aluminum Alloy
Product Category	Clevis Bail
Type	Automatic
UPC	096359308980

Dimensions

Length	12.900 in
Weight	0.630 lb
Width	1.750 in

Conductor Related

Conductor Compatibility	ACSR-Swan-4-6/1;ACSR-Sparrow-2-6/1;AAC-Rose-4-7;AAC-Iris-2-7;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18
Conductor Diameter - Maximum	0.32
Conductor Diameter - Minimum	0.22
Conductor Diameter Range	0.22 - 0.32

Logistics

Pallet Quantity	2100
-----------------	------

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - Deadends For Overhead Connections \(LEEDS-HPS-DEADEND-QUICK-REFERENCE-GUIDE-SF-EN-2023_Web\)](#)
[Sales Drawings - CC-25241](#)

Related Products

[GD4642A - Aluminum Automatic Dead End, #4 - #2 AAC, #4 - #2 AAAC, #4 - #2 ACSR Conductor, Semi-Flex Bail.](#)
[GD4042AZ - Aluminum Automatic Dead End, #4 - #2 AAC, #4 - #2 AAAC, #4 - #2 ACSR Conductor, Z Bail.](#)
[GD4042A - Aluminum Automatic Dead End, #4 - #2 AAC, #4 - #2 AAAC, #4 - #2 ACSR Conductor, SS Flex Bail.](#)