

**Aluminum Automatic Dead End,  
397.5 AAC, 394.5 AAAC, 336.4  
(18/1) ACSR Conductor, Clevis Bail.**

By FARGO  
Catalog # [GD451](#)

Aluminum Automatic Dead End, 397.5 AAC, 394.5 AAAC, 336.4 (18/1) ACSR Conductor, Diameter range .659 - .724" (16.74 - 18.39 mm), Clevis Bail.


**Features**

- Automatic Dead Ends for ACSR, AAC, and AAAC Conductor
- Galvanized steel stirrup clevis or Z-bail for primary applications and flexible or semi-flex bails for secondary applications
- Add "N" for neoprene covered Flex or Semi-flex bail
- Add "TA" for pulling eye (clevis bail only)

**General**

Bail Option	Clevis Bail
Catalog Number	GD451
Color Code	Green
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum
Material - Bail	Galvanized Steel
Material - Pin (Clevis)	Galvanized Steel
Material - Pin (Cotter)	Stainless Steel
Material - Shell	High Strength Aluminum Alloy
Product Category	Clevis Bail
Type	Automatic
UPC	096359309130

**Dimensions**

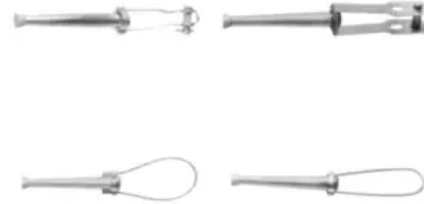

\*Representative Image

Assembly Rating (Ultimate)	10000 lb
Weight	2.74 lb

**Conductor Related**

Conductor Compatibility	ACSR-Ostrich-300-26/7;ACSR-Merlin-336.4-18/1;ACSR-Linnet-336.4-26/7;ACSR-Brahma-203.2-16/19;AAC-Daffodil-350-19
Conductor Diameter - Maximum	0.724
Conductor Diameter - Minimum	0.659
Conductor Diameter Range	0.659 - 0.724

**Logistics**

Pallet Quantity	320
-----------------	-----

**Product Assets**

- [Catalogs - Distribution Connectors](#)
- [Literature - Ropes Course Industry Letter \(April 2021\)](#)
- [Literature - Deadends For Overhead Connections](#)
- [Sales Drawings - GD-440A\\_Series\\_Overhead\\_Automatic\\_Deadend\(CC-25241\)](#)
- [Specifications - GD451](#)