

**Aluminum Automatic Dead End, #4
- #2 AAC, #4 - #2 AAAC, #4 - #2
ACSR Conductor, Semi-Flex Bail.**

By FARGO
Catalog # [GD4642A](#)

Aluminum Automatic Dead End, #4 - #2 AAC, #4 - #2 AAAC, #4 - #2 ACSR Conductor, Diameter range .220 - .320" (5.59 - 8.13 mm), Semi-Flex Bail.

Features


- Automatic Dead Ends for ACSR, AAC, and AAAC Conductor
- Galvanized steel stirrup clevis or Z-bail for primary applications and flexible or semi-flex bails for secondary applications
- Add "N" for neoprene covered Flex or Semi-flex bail
- Add "TA" for pulling eye (clevis bail only)

General

Bail Option	Semi-Flex Bail
Catalog Number	GD4642A
Color Code	Red; Orange
Material	Aluminum
Material - Bail	Stainless Steel
Material - Shell	High Strength Aluminum Alloy
Product Category	Semi-Flex Bail
Type	Automatic
UPC	096359309192

Dimensions

Assembly Rating (Ultimate)	0 lb
Length	14.4 in
Weight	0.38 lb
Width	2.2 in

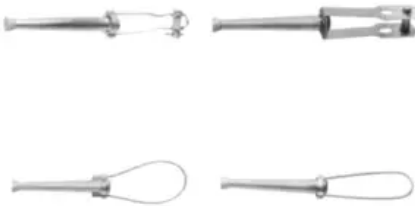

*Representative Image

Conductor Related

Conductor Compatibility	ACSR-Swan-4-6/1;ACSR-Sparrow-2-6/1;AAC-Rose-4-7;AAC-Iris-2-7;AAAC 6201 Alloy-Alton-48.69-6/18;AAAC 6201 Alloy-Ames-77.47-6/18
Conductor Diameter - Maximum	0.32
Conductor Diameter - Minimum	0.22
Conductor Diameter Range	0.22 - 0.32

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	---

Logistics

Pallet Quantity	4200
-----------------	------

Product Assets

- [Catalogs - Distribution Connectors](#)
- [Literature - Deadends For Overhead Connections](#)
- [Literature - Ropes Course Industry Letter \(April 2021\)](#)
- [Sales Drawings - CC-25241](#)
- [Specifications - GD4642A](#)