


## Tie, Insulator Side

By FARGO  
Catalog # [GJ654FC](#)

Composite Side Tie, Loop Center

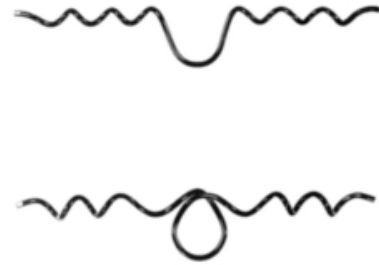

\*Representative Image

### Features

- Semi-Conductive tie provides uniform electrical field around attachment point.

### General

Color Code	Orange
EU RoHS Indicator	No
Insulator Throat Neck Type	C Neck
Material	Composite
Material - Cover and Body	Semi-Conductive covering over Rigid Black PVC
Product Category	Ties
UPC	096359310761

### Dimensions

Insulator Throat Diameter - Maximum	2.75 in
Insulator Throat Diameter - Minimum	2.12 in
Insulator Throat Diameter Range	2.12 - 2.75
Length	25.000 in
Weight	0.314 lb

### Conductor Related

Conductor Diameter (Covered) - Maximum	0.919 in
Conductor Diameter (Covered) - Minimum	0.718 in
Conductor Diameter (Covered) Range	0.919-0.718
Conductor Diameter - Maximum	0.919
Conductor Diameter - Minimum	0.718 in
Conductor Diameter Range	0.718 - 0.919
Conductor Type	Covered

### Logistics

Carton Quantity	100
Pallet Quantity	600

### Product Assets

[Sales Drawings - GJ600 Composite Side Tie](#)