


## Automatic Splice Copper

By FARGO  
Catalog # [GL110](#)

Automatic Splice, for #8 SOL Copper, Dia. Range 0.12 - 0.13 in.

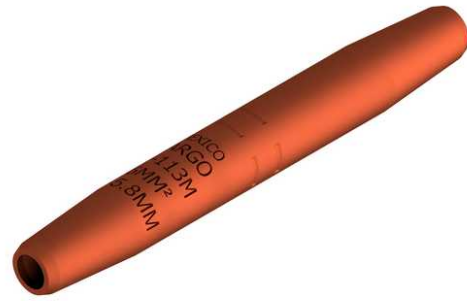

\*Representative Image

### Features

- Fastest method of splicing copper and copperweld conductor
- Individually bagged to seal out dirt before use
- Inhibitor protected for optimum long term performance
- ANSI C19.4 Class 1A Normal tension Connector (60% RBS)

### General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311201

### Dimensions

Dimensions	3.400 in x 0.500 in x 0.500 in
Height	0.500 in
Length	3.400 in
Weight	0.110 lb
Width	0.500 in

### Conductor Related

Conductor Diameter - Maximum	0.13
Conductor Diameter - Minimum	0.12
Conductor Diameter Range	0.12 - 0.13
Conductor Type	Copper, Copperweld

### Certifications and Compliance

UL Listed	No
-----------	----

### Logistics

Pallet Quantity	21000
-----------------	-------

### Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Sales Drawings - Sales Drawing \(CC-25239\)](#)