


HUBBELL

Power Systems

Automatic Splice, Copper

By FARGO
Catalog # [GL110M](#)

Automatic Splice, for 6 MM2 Copper, Dia. Range 0.10 - 0.14 in.

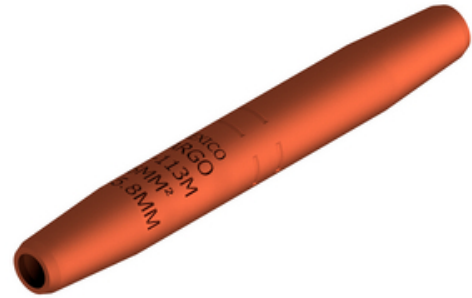

*Representative Image

Features

- Range taking automatic splice
- For use with copper and Copperweld conductor
- Individually bagged to seal out dirt before use
- ANSI C119.4 Class 1A normal tension connector (60% of conductor breaking strength)

General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359459859

Conductor Related

Conductor Diameter - Maximum	0.14
Conductor Diameter - Minimum	0.1
Conductor Diameter Range	0.1 - 0.14
Conductor Type	Copper, Copperweld

Certifications And Compliance

UL Listed	No
-----------	----

Logistics

Carton Quantity	100
Pallet Quantity	17500

Product Assets

[Catalogs - Distribution Connectors](#)
[Sales Drawings - Sales Drawing](#)
[Sales Drawings - Overhead Line Splices Metric Copper Conductors \(For Reference Only\)](#)



A Hubbell brand