


# HUBBELL

## Power Systems

### Automatic Splice Copper

By FARGO  
Catalog # [GL111](#)

Automatic Splice, for #6 SOL Copper, 3 #12 Copperweld, Dia.  
Range 0.16 - 0.17 in.

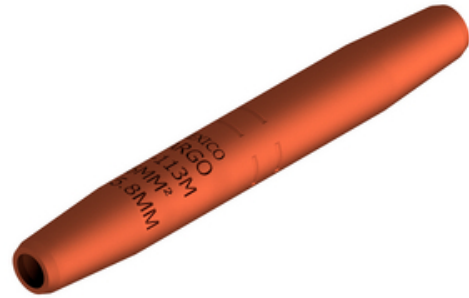

\*Representative Image

#### Features

- Fastest method of splicing copper and copperweld conductor
- Individually bagged to seal out dirt before use
- Inhibitor protected for optimum long term performance
- ANSI C19.4 Class 1A Normal tension Connector (60% RBS)

#### General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311218

#### Dimensions

Dimensions	3.400 in x 0.500 in x 0.500 in
Height	0.5 in
Length	3.4 in
Weight	0.11 lb
Width	0.5 in

#### Conductor Related

Conductor Diameter - Maximum	0.17
Conductor Diameter - Minimum	0.16
Conductor Diameter Range	0.16 - 0.17
Conductor Type	Copper, Copperweld

#### Certifications And Compliance

UL Listed	No
-----------	----

#### Logistics

Pallet Quantity	21000
-----------------	-------

#### Product Assets

[Catalogs - Distribution Connectors](#)  
[Sales Drawings - Sales Drawing](#)



A Hubbell brand