


Automatic Splice, Copper

By FARGO
Catalog # [GL114M](#)

Automatic Splice, for 25 MM² Copper, Dia. Range 0.22 - 0.26 in.

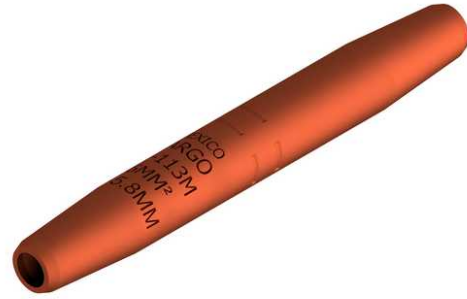

*Representative Image

Features

- Range taking automatic splice
- For use with copper and Copperweld conductor
- Individually bagged to seal out dirt before use
- ANSI C119.4 Class 1A normal tension connector (60% of conductor breaking strength)

General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311379

Conductor Related

Conductor Diameter - Maximum	0.26
Conductor Diameter - Minimum	0.22
Conductor Diameter Range	0.22 - 0.26
Conductor Type	Copper, Copperweld

Certifications and Compliance

UL Listed	No
-----------	----

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Sales Drawings - Sales Drawing \(CC-25239\)](#)
[Sales Drawings - Overhead Line Splices Metric Copper Conductors \(For Reference Only\)](#)