


Automatic Splice Copper

By FARGO
Catalog # [GL116](#)

Automatic Splice, for 1/0 SOL or #1 (7 str), #2 (3 str) Copper,
3A Copperweld, Dia. Range 0.32 - 0.33 in.

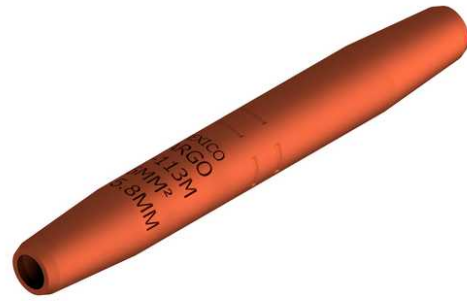

*Representative Image

Features

- Fastest method of splicing copper and copperweld conductor
- Individually bagged to seal out dirt before use
- Inhibitor protected for optimum long term performance
- ANSI C19.4 Class 1A Normal tension Connector (60% RBS)

General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311409

Dimensions

Dimensions	4.400 in x 0.750 in x 0.750 in
Height	0.750 in
Length	4.400 in
Weight	0.290 lb
Width	0.750 in

Conductor Related

Conductor Diameter - Maximum	0.33
Conductor Diameter - Minimum	0.32
Conductor Diameter Range	0.32 - 0.33
Conductor Type	Copper, Copperweld

Certifications and Compliance

UL Listed	No
-----------	----

Logistics

Pallet Quantity	8000
-----------------	------

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Sales Drawings - Sales Drawing \(CC-25239\)](#)