


# HUBBELL

## Power Systems

### Automatic Splice, Copper

By FARGO  
Catalog # [GL118M](#)

Automatic Splice, for 2/0 SOL, 3/0 SOL, 1/0 (7 str), 2/0 (7 str),  
70 MM2 Copper, Dia. Range 0.36 - 0.43 in.

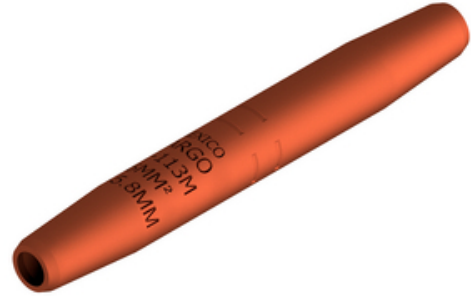

\*Representative Image

#### Features

- Range taking automatic splice
- For use with copper and Copperweld conductor
- Individually bagged to seal out dirt before use
- ANSI C119.4 Class 1A normal tension connector (60% of conductor breaking strength)

#### General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311485

#### Conductor Related

Conductor Diameter - Maximum	0.43
Conductor Diameter - Minimum	0.36
Conductor Diameter Range	0.36 - 0.43
Conductor Type	Copper, Copperweld

#### Certifications And Compliance

UL Listed	No
-----------	----

#### Product Assets

[Catalogs - Distribution Connectors](#)  
[Sales Drawings - Sales Drawing](#)  
[Sales Drawings - Overhead Line Splices Metric Copper Conductors \(For Reference Only\)](#)