


# HUBBELL

## Power Systems

### Automatic Splice Copper

By FARGO  
Catalog # [GL119](#)

Automatic Splice, for 4/0 SOL or 3/0 (7) Copper, Dia. Range  
0.45 - 0.46 in.

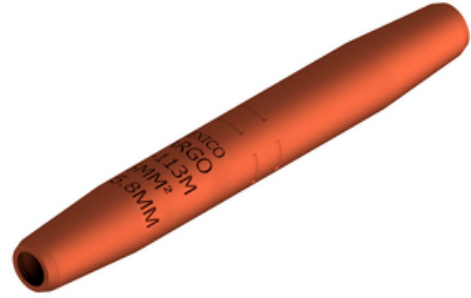

\*Representative Image

#### Features

- Fastest method of splicing copper and copperweld conductor
- Individually bagged to seal out dirt before use
- Inhibitor protected for optimum long term performance
- ANSI C19.4 Class 1A Normal tension Connector (60% RBS)

#### General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311492

#### Dimensions

Dimensions	6.900 in x 1.200 in x 1.200 in
Height	1.2 in
Length	6.9 in
Weight	1 lb
Width	1.2 in

#### Conductor Related

Conductor Diameter - Maximum	0.46
Conductor Diameter - Minimum	0.45
Conductor Diameter Range	0.45 - 0.46
Conductor Type	Copper, Copperweld

#### Certifications And Compliance

UL Listed	No
-----------	----

#### Product Assets

[Catalogs - Distribution Connectors](#)  
[Sales Drawings - Sales Drawing](#)



A Hubbell brand