


HUBBELL

Power Systems

Automatic Splice Copper

By FARGO
Catalog # [GL120](#)

Automatic Splice, for 4/0 (7 or 19 str) Copper, Dia. Range 0.52 - 0.53 in.

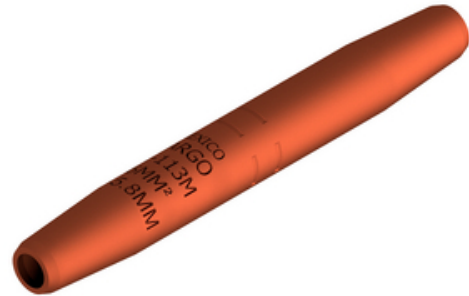

*Representative Image

Features

- Fastest method of splicing copper and copperweld conductor
- Individually bagged to seal out dirt before use
- Inhibitor protected for optimum long term performance
- ANSI C19.4 Class 1A Normal tension Connector (60% RBS)

General

| | |
|--------------------------|----------------------|
| Color Code | None |
| EU RoHS Indicator | Contact Manufacturer |
| Material | Copper |
| Material - Gripping Unit | Bronze Alloy |
| UPC | 096359311546 |

Dimensions

| | |
|------------|--------------------------------|
| Dimensions | 6.900 in x 1.200 in x 1.200 in |
| Height | 1.2 in |
| Length | 6.9 in |
| Weight | 1 lb |
| Width | 1.2 in |

Conductor Related

| | |
|------------------------------|--------------------|
| Conductor Diameter - Maximum | 0.53 |
| Conductor Diameter - Minimum | 0.52 |
| Conductor Diameter Range | 0.52 - 0.53 |
| Conductor Type | Copper, Copperweld |

Certifications And Compliance

| | |
|-----------|----|
| UL Listed | No |
|-----------|----|

Logistics

| | |
|-----------------|------|
| Pallet Quantity | 2400 |
|-----------------|------|

Product Assets

[Catalogs - Distribution Connectors](#)
[Sales Drawings - Sales Drawing](#)



A Hubbell brand