


Automatic Splice Copper

By FARGO
Catalog # [GL125](#)

Automatic Splice, for 350 (19 str) Copper, Dia. Range 0.67 - 0.68 in.

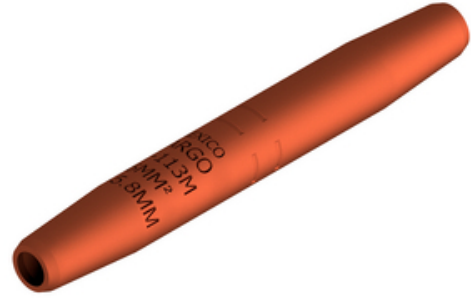

*Representative Image

General

Color Code	None
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311607

Conductor Related

Conductor Diameter - Maximum	0.68
Conductor Diameter - Minimum	0.67
Conductor Diameter Range	0.67 - 0.68
Conductor Type	Copper, Copperweld

Certifications And Compliance

UL Listed	No
-----------	----

Logistics

Pallet Quantity	900
-----------------	-----

Product Assets

[Catalogs - Distribution Connectors](#)
[Sales Drawings - Sales Drawing](#)