


HUBBELL Power Systems

Mid Span Tap

By FARGO
Catalog # [GM102A](#)

Mid Span Tap

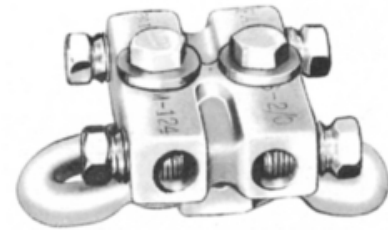

*Representative Image

Features

- A wide angle bell mouth opening permits tap offs up to 45° in either direction from the center line of the clamp.
- Long, contoured contact surfaces protect the neutral from the pull of the service.

General

Bolt Installation Torque (Recommended)	0 ft-lbs
Catalog Number	GM102A
EU RoHS Indicator	No
Material	Aluminum Alloy
Material - Body	Aluminum Alloy
Material - Body Halves	Aluminum Alloy
Material - Bolt	Stainless Steel
Material - Hardware	Aluminum Alloy
Product Category	Midspan
Style	Side Loop Connection
Type	Bolted
UPC	096359312321

Dimensions

Actual Clamp Strand Diameter Range	0 in
Adjustment Step	0 in
Angle - Pad	0 °
Dimensions	3.380 in x 1.500 in x 2.750 in
Height	2.75 in
Length	3.38 in
Weight	0.43 lb
Width	1.5 in

Conductor Related

Conductor Diameter - Maximum	0.563
Conductor Diameter - Minimum	0.198
Conductor Diameter Range	0.198 - 0.563

Logistics

Carton Quantity 50

Product Assets

[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - CC-26215](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
FG-GM102A-SPEC-EN | REV 6/2024