


HUBBELL

Power Systems

Formed Wire Double Side Tie, C & F Neck Insulator

By FARGO
Catalog # [LLDU4162AS](#)

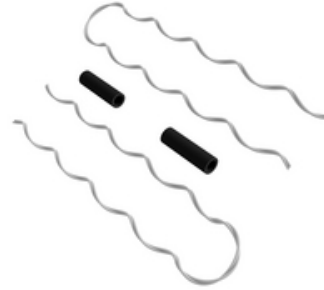

C & F Neck Insulator Double Side Tie for 556.5 and 636 ACSR-636 and 700 AAC

Features

- For securing the conductor in the side groove of insulators on line angles between (0°) zero degrees and (80°) eighty degrees with no more than a (40°) forty degree angle at each insulator.
- C-Neck (2-1/4" neck diameter) & F-Neck (2-7/8" neck diameter) interchangeable headstyle insulators
- Recommended for use with ANSI Class 55-2 Pin, 55-3 Pin, 55-4 Pin, 55-5 Pin, 57-1 Post, 57-2 Post, & 57-3 Post Insulators.

General

Application	Double Side Tie
Color Code	Blue
EU RoHS Indicator	No
Insulator Throat Neck Type	C & F Neck
Material	Aluminum Clad Steel
Product Category	Ties
Type	Formed Wire
UPC	096359452744

Dimensions

Length	22 in
Weight	.840 lb

Conductor Related

Conductor Diameter - Maximum	0.968
Conductor Diameter - Minimum	0.859
Conductor Diameter Range	0.859 - 0.968
Conductor Type	ACSR, AAC, AAAC, ACAR, Compacted ACSR and AWAC®

Logistics

Carton Quantity	50
Pallet Quantity	600

Product Assets

[Sales Drawings - LLDU4, LLDU5 Drawing](#)
[Video - Hubbell Power Systems Double Side Tie Installation](#)



A Hubbell brand