


# HUBBELL

## Power Systems

### Formed Wire Double Side Tie, J-Neck Insulator

By FARGO  
Catalog # [LLDU5155AS](#)

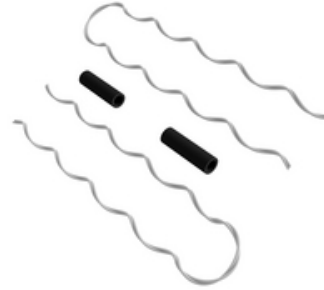

J-Neck Insulator Double Side Tie for 1/0 ACSR, 1/0 AAC and 1/0 AAAC

#### Features

- For securing the conductor in the side groove of insulators on line angles between (0°) zero degrees and (80°) eighty degrees with no more than a (40°) forty degree angle at each insulator.
- J-Neck (3-1/2" neck diameter) interchangeable headstyle insulators
- Recommended for use with ANSI Class 55-6 Single Skirt Pin, 55-7 Single Skirt Pin & 56-1 Double Skirt Pin Insulators.

#### General

Application	Double Side Tie
Color Code	Yellow
EU RoHS Indicator	No
Insulator Throat Neck Type	J Neck
Material	Aluminum Clad Steel
Product Category	Ties
Type	Formed Wire
UPC	096359472988

#### Dimensions

Length	21 in
Weight	.520 lb

#### Conductor Related

Conductor Diameter - Maximum	0.405
Conductor Diameter - Minimum	0.358
Conductor Diameter Range	0.358 - 0.405
Conductor Type	ACSR, AAC, AAAC, ACAR, Compacted ACSR and AWAC®

#### Logistics

Carton Quantity	50
Pallet Quantity	800

#### Product Assets

[Sales Drawings - LLDU4, LLDU5 Drawing](#)  
[Video - Hubbell Power Systems Double Side Tie Installation](#)



A Hubbell brand