


Formed Wire Double Side Tie, J-Neck Insulator

By FARGO
Catalog # [LLDU5163AS](#)

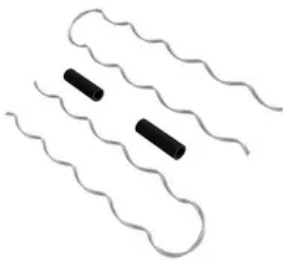

J-Neck Insulator Double Side Tie for 636, 715.5 and 795 ACSR;
795 AAC

Features

- For securing the conductor in the side groove of insulators on line angles between (0°) zero degrees and (80°) eighty degrees with no more than a (40°) forty degree angle at each insulator.
- J-Neck (3-1/2" neck diameter) interchangeable headstyle insulators
- Recommended for use with ANSI Class 55-6 Single Skirt Pin, 55-7 Single Skirt Pin & 56-1 Double Skirt Pin Insulators.

Application

Double Side Tie

General

Catalog Number	LLDU5163AS
Color Code	Green
Insulator Throat Neck Type	J Neck
Material	Aluminum Clad Steel
Product Category	Ties
Type	Formed Wire
UPC	096359473008

Dimensions

Length	23 in
Weight	.860 lb

Conductor Related

Conductor Diameter - Maximum	1.096
Conductor Diameter - Minimum	0.969
Conductor Diameter Range	0.969 - 1.096
Conductor Type	ACSR, AAC, AAAC, ACAR, Compacted ACSR and AWAC®

Logistics

Carton Quantity	50
Pallet Quantity	800

Product Assets

[Sales Drawings - LLDU4, LLDU5 Drawing](#)
[Specifications - LLDU5163AS](#)
[Video - Hubbell Power Systems Double Side Tie Installation](#)