


Formed Wire Spool Tie

By FARGO
Catalog # [LRO4018AS](#)

Spool Tie for 1/0 ACSR, 1/0 AAC, 1/0 AAAC- #4, #3 and #2
Plastic Jacketed

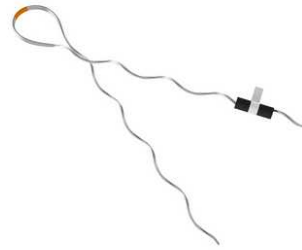

Features

- For securing the conductor in the side groove of horizontally or vertically mounted spool insulators.
- For 1-3/4" neck diameter interchangeable headstyle insulators
- Recommended for use with ANSI Class 53-1, 53-2 & 53-3 Spool Insulators.

Application

Spool Tie

General

Color Code	Yellow
EU RoHS Indicator	No
Insulator Throat Neck Type	Spool
Material	Aluminum Clad Steel
Product Category	Ties
Type	Formed Wire
UPC	096359452546

Dimensions

Length	26 in
Weight	.240 lb

Conductor Related

Conductor Diameter - Maximum	0.405
Conductor Diameter - Minimum	0.358
Conductor Diameter Range	0.358 - 0.405
Conductor Type	ACSR, AAC, AAAC, ACAR, Compacted ACSR and AWAC®

Logistics

Carton Quantity	100
Pallet Quantity	2000

Product Assets

[Sales Drawings - LRO Drawing](#)

[Video - Hubbell Power Systems Quick Spool Tie Installation \(VI05013E\)](#)

[Video - Hubbell Power Systems - Spool Tie Installation \(VI05016E\)](#)