


Formed Wire Spool Tie

By FARGO
Catalog # [LRO4030AS](#)

Spool Tie for 397.5 and 477 ACSR; 450, 477, 500 and 556.5 AAC; 266.8 and 336.4 Plastic Jacketed

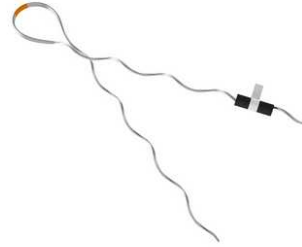

Features

- For securing the conductor in the side groove of horizontally or vertically mounted spool insulators.
- For 1-3/4" neck diameter interchangeable headstyle insulators
- Recommended for use with ANSI Class 53-1, 53-2 & 53-3 Spool Insulators.

Application

Spool Tie

General

Color Code	Red
Insulator Throat Neck Type	Spool
Material	Aluminum Clad Steel
Product Category	Ties
Type	Formed Wire
UPC	096359467915

Dimensions

Length	26 in
Weight	.500 lb

Conductor Related

Conductor Diameter - Maximum	0.858
Conductor Diameter - Minimum	0.756
Conductor Diameter Range	0.756 - 0.858
Conductor Type	ACSR, AAC, AAAC, ACAR, Compacted ACSR and AWAC®

Logistics

Carton Quantity	50
Pallet Quantity	500

Product Assets

[Sales Drawings - LRO Drawing](#)

[Video - Hubbell Power Systems Quick Spool Tie Installation \(VI05013E\)](#)

[Video - Hubbell Power Systems - Spool Tie Installation \(VI05016E\)](#)