


Formed Wire Spool Tie

By FARGO
Catalog # [LRO4031AS](#)

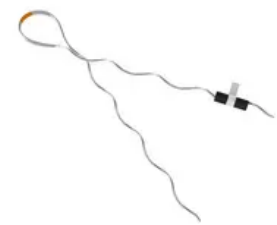

Spool Tie for 556.5 and 636 ACSR; 636 and 700 AAC; 350, 336.4, 450 and 477 Plastic Jacketed

Features

- For securing the conductor in the side groove of horizontally or vertically mounted spool insulators.
- For 1-3/4” neck diameter interchangeable headstyle insulators
- Recommended for use with ANSI Class 53-1, 53-2 & 53-3 Spool Insulators.

Application

Spool Tie

General

Catalog Number	LRO4031AS
Color Code	Blue
Insulator Throat Neck Type	Spool
Material	Aluminum Clad Steel
Product Category	Ties
Type	Formed Wire
UPC	096359467939

Dimensions

Length	28 in
Weight	.520 lb

Conductor Related

Conductor Diameter - Maximum	0.968
Conductor Diameter - Minimum	0.859
Conductor Diameter Range	0.859 - 0.968
Conductor Type	ACSR, AAC, AAAC, ACAR, Compacted ACSR and AWAC®

Logistics

Carton Quantity	50
Pallet Quantity	500

Product Assets

- [Sales Drawings - LRO Drawing](#)
- [Specifications - LRO4031AS](#)
- [Video - Hubbell Power Systems - Spool Tie Installation](#)
- [Video - Hubbell Power Systems Quick Spool Tie Installation](#)