


Grounding Clamp

by ANDERSON
Catalog ID: GC11113C

Grounding Clamp, Copper Cable to Rod or Tube, U-bolt style. GROUND, BRZ BOLT, .204-.419 IN, 5 IPS

- Everdur hardware supplied by adding Suffix ED

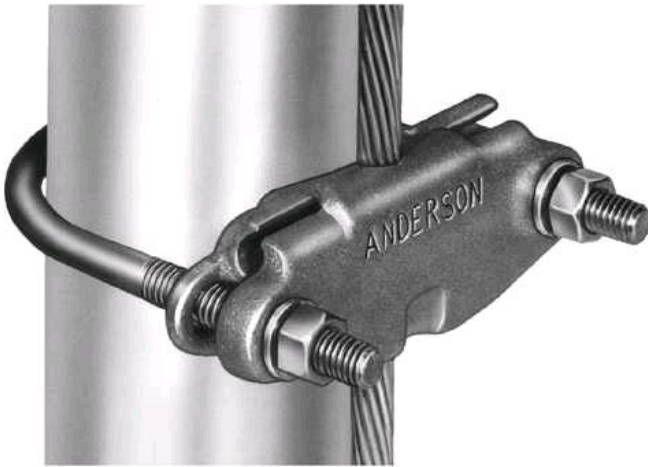

* Representative image

Product Details

General

Bolt Installation Torque (Recommended)	0 ft-lbs
Material	Bronze
Material - Hardware	Stainless Steel
UPC	096359305798

Dimensions

Diameter - Clamping Hardware	5 in
Diameter - Rod / Tube	5 in
Diameter - Rod / Tube Outside	5.625 in
Weight	3.724 lb

Conductor Related

Conductor Diameter - Maximum	0.575 in
Conductor Diameter - Minimum	0.365 in
Conductor Diameter Range	0.365 - 0.575
Conductor Type	Copper

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscsc@hubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com