




Automatic Splice Copper

by FARGO
Catalog ID: GL115M

Automatic Splice, for #2 SOL, #1 SOL, 1/0 SOL, #2 7 str, 35 MM2 Str
Copper, Dia. Range 0.25 - 0.30 in.

- Range taking automatic splice
- For use with copper and Copperweld conductor
- Individually bagged to seal out dirt before use

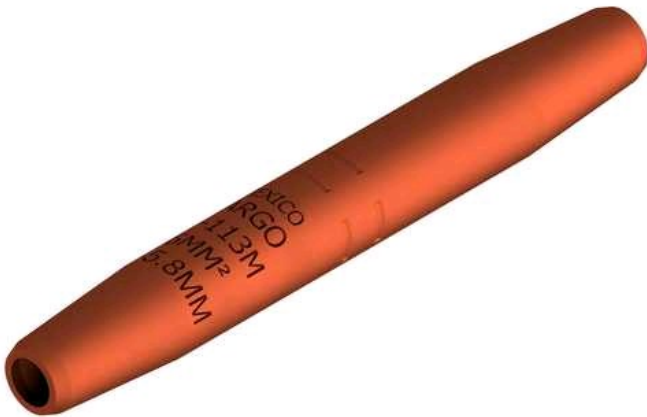

* Representative image

Product Details

General

Color Code	None
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311393

Conductor Related

Conductor Diameter - Maximum	0.30 in
Conductor Diameter - Minimum	0.25 in
Conductor Diameter Range	0.25 - 0.30
Conductor Type	Copper, Copperweld

Certifications and Compliance

UL Listed	No
-----------	----

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscs@hubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com