




Automatic Splice Copper

by FARGO
Catalog ID: GL123

Automatic Splice, for 300 (19 or 37 str) Copper, Copperweld, Dia. Range 0.62 - 0.63 in.

- Individually bagged to seal out dirt before use.

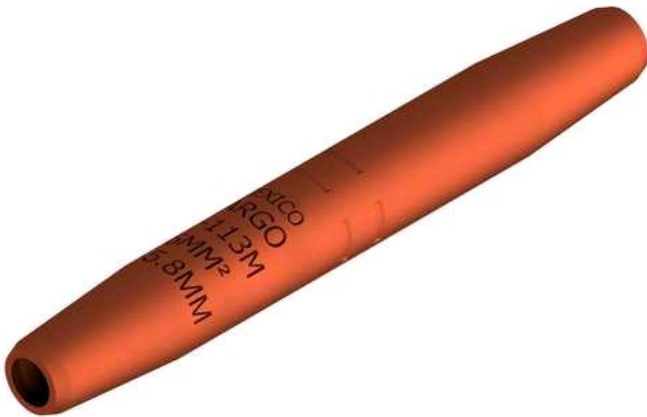

* Representative image

Product Details

General

Color Code	None
Material	Copper
Material - Gripping Unit	Bronze Alloy
UPC	096359311591

Conductor Related

Conductor Diameter - Maximum	0.63 in
Conductor Diameter - Minimum	0.62 in
Conductor Diameter Range	0.62 - 0.63
Conductor Type	Copper, Copperweld

Certifications and Compliance

UL Listed	No
-----------	----

Logistics

Pallet Quantity	900 EA
-----------------	--------

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscscs@hubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com