




# 162P-IVR GRP ASSY 3.44R BLACK

By Gleason Reel  
Catalog # [162P-IVR-3.4](#)

162P-IVR GRP ASSY 3.44R BLACK

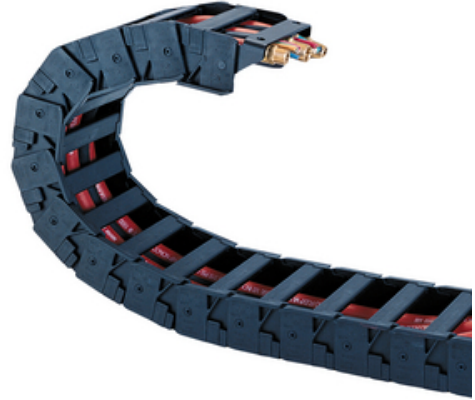

## Features

- Compact design, Snap-Together links, Non-conductive, Resists corrosion

## General

Series PowerTrak GRP  
Type Flip-Top Track

## Dimensions

|                 |         |
|-----------------|---------|
| Bend (Radius)   | 7.85 in |
| Curve Length    | 1.5 ft  |
| Height          | 1.62 in |
| Height - Window | 1 in    |
| Mounting Height | 8.5 in  |
| Pitch           | 1.81 in |
| Weight          | 0.84 lb |
| Width           | 5.01 in |
| Width - Window  | 4.06 in |

## Conductor Related

Diameter - Cable Outside 0.83 in

## Product Assets

[Brochures - GLEASON\\_GRPtrak\\_BROCHURE](#)  
[Installation Manuals - GRP Instructions - All Models 046823](#)  
[Installation Manuals - Cable/Hose Guidelines 043181](#)  
[Technical Solutions - GRD-162P-IVR-3.4-SPEC-EN](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
GRD-162P-IVR-3.4-SPEC-EN | REV 1/2024