




EFV Model P70 with SERIES 1800

By Gas Breaker
Catalog # [20306GB](#)

EFV #P70 2" PERF. SADDLE TEE X 3/4" IPS, 12" LONG, 2406, SERIES 1800

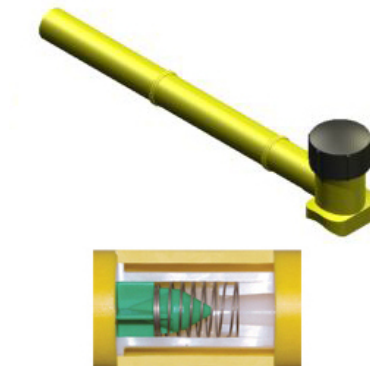

Features

- Work with the flow of natural gas as the sensing source
- Activate when a line rupture causes an excess flow condition
- Automatically reset and resume normal operation after repairs are made using a slight gas bypass to re-pressurize the line. Install in minutes with standard tools
- Operate within your normal service line sizing requirements to avoid tripping by snap-acting loads
- Higher capacity EFVs can accommodate future increases in gas loads.
- Maintain stability under turbulent flow conditions by using a unique, dynamically balanced float
- Available for virtually all pressures and service line capabilities

- In-line installation makes them tamper-proof
- Can be fabricated with fitting and piping materials from most manufacturers

General

Catalog Number	20306GB
Material	PE Polyethylene (2406/2708)

Product Assets

[Catalogs - Gas Breaker - Automatic Safety Valves for Gas Service Lines](#)
[Specifications - 20306GB](#)



A Hubbell brand

©2025 Hubbell Incorporated. All rights reserved
GSBK-20306GB-SPEC-EN | REV 3/2025