

# CAPTIVATE™

ILLUMINATED MIRROR LIGHT

## FEATURES

- Perimeter etched panels are indirectly backlit to provide uniform illumination
- Available in four sizes (18"x39", 25"x43", 31"x43" and 37"x43")
- Mirror edges have brushed, radius treatment for consistency in appearance
- Optional integrated night light in white (3000K) or amber (590nm) is located in the lower horizontal window
- Simple mounting of the housing and mirror
- All models are ADA compliant
- Standard with 0–10V dimming



## SPECIFICATIONS

### CONSTRUCTION

- One-piece 18-gauge CRS housing and powder coated brackets
- The mirror is 0.25" thick with etched windows for backlighting
- The housing has a white, polyester powder coat paint with an antimicrobial additive to inhibit the growth of microbes

### OPTICS

- LEDs are mounted around the perimeter of the housing to provide indirect backlighting for enhanced uniformity
- Available in three different CCTs (3000K, 3500K and 4000K) with a CRI of > 80. Captivate is standard with 0–10V dimming
- The night light option is available for all sizes and is mounted in the housing

### OPTICS (CONTINUED)

- It is available in either white (3000K) or amber (590nm) and for 120–277V

### INSTALLATION

- Housing is surface mounted with four mounting points
- Mirror brackets attach to the housing with safety screws to lock the mirror in place
- A perimeter gasket between the housing and mirror ensures soft contact and prevents damage to the mirror

### ELECTRICAL

- Available with Universal-Voltage (120–277V, 50/60 Hz)

### CERTIFICATION

- Built and tested to UL1598 standard and bears the cCSAus label for Damp Locations

### WARRANTY

- 5 year warranty
- See [HLI Standard Warranty](#) for additional information

## ORDERING GUIDE

**Example:** CML1–3143–830–U–NA

 CATALOG # 



CML1		8		U	
Model	Size	CRI	Color Temp	Voltage	Options
CML1 Captivate Mirror Light	1839 18"W x 39"H (nom.) 2543 25" x 43" (nom.) 3143 31" x 43" (nom.) 3743 37" x 43" (nom.)	8 > 80	30 3000K 35 3500K 40 4000K	U Universal (120–277)	NW Night light-white (3000K) NA Night light-amber (590nm) TR Tamper-resistant hardware

KEY DATA	
Lumen Range	912–1,689
Wattage Range	24.9–35.9
Efficacy Range (LPW)	36.6–47
Reported Life (Hours)	L80/60,000
Input Current Range (mAmps)	88–304

# CAPTIVATE™

ILLUMINATED MIRROR LIGHT

## DIMENSIONS

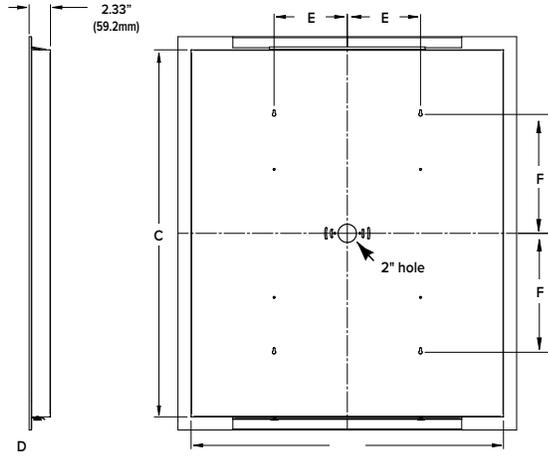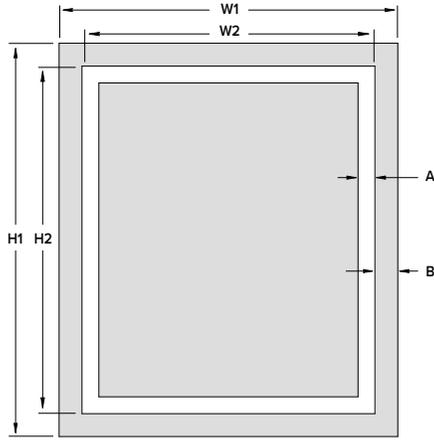

	Model #			
	1839	2543	3143	3743
H1	39.0" (990.6mm)	43.0" (1092.2mm)	43.0" (1092.2mm)	43.0" (1092.2mm)
H2	31.3" (795.0mm)	34.3" (992.0mm)	34.3" (992.0mm)	34.3" (992.0mm)
W1	17.7" (449.6mm)	24.7" (627.4mm)	31.0" (787.4mm)	37.0" (939.8mm)
W2	10.0" (254.0mm)	16.0" (406.4mm)	22.3" (566.4mm)	28.3" (718.8mm)
A	1.8" (45.7mm)	1.8" (45.7mm)	1.8" (45.7mm)	1.8" (45.7mm)
B	2.0" (50.8mm)	2.5" (50.8mm)	2.5" (50.8mm)	2.5" (50.8mm)
C	37.1" (942.3mm)	40.1" (1018.5mm)	40.1" (1018.5mm)	40.1" (1018.5mm)
D	15.8" (401.3mm)	21.8" (553.7mm)	28.1" (713.7mm)	34.1" (916.9mm)
E	7.4" (188.0mm)	5.0" (127.0mm)	8.0" (203.2mm)	8.0" (203.2mm)
F	13.0" (330.2mm)	13.0" (330.2mm)	13.0" (330.2mm)	13.0" (330.2mm)

Model #	3500K			INPUT CURRENT	
	Lumen	Wattage	LPW	With Mirror	
				120V	277V
1839	912	24.9	36.6	0.208 A	0.088 A
2543	1140	24.4	46.7	0.205 A	0.088 A
3143	1653	36.2	45.7	0.304 A	0.131 A
3743	1689	35.9	47.0	0.302 A	0.130 A